


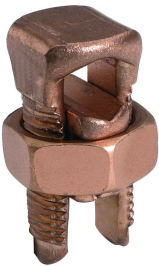

KS31, Split Bolt Connector, Run/Tap: 1/0 AWG Str-350 kcmil

By Burndy
Catalog # [KS31](#)

Copper Split Bolt, Cu: 1/0 AWG (Str)-350 kcmil (Run & Tap)



Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Cables

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	• UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	• UL 486A • UL486B
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	5
Conductor - Rebar Size Range	5
Conductor - Copper Str Run Range	1/0 STR - 350 KCMIL
Conductor - Copper Str Run	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - Copper Solid Run Range	1/0 -350 kcmil
Conductor - Copper Solid Run	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil

Conductor - Copper Solid Tap Range	• 300 kcmil • 350 kcmil
Conductor - Copper Solid Tap	1/0 -350 kcmil
Conductor - CopperWeld Str Tap Range	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil
Conductor - CopperWeld Str Tap	19 #8
Conductor - CopperWeld Str Run Range	19 #8
Conductor - CopperWeld Str Run	19 #8
Conductor Type	• CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	1/0 STR - 350 KCMIL
Conductor - Copper Str Tap	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

Dimension - L Length Overall mm	64 mm
Width	1.41 in
Dimension - Width fraction	1-41/100 in
Dimension - B Length fraction	1-1/4 in
Dimension - Width mm	36 mm
Dimension - Width inch	1.41 in
Dimension - B Length inch	1.25 in
Dimension - Cross Flats inch	1.70 in
Dimension - Length Overall inch	2.6

Force Related

Installation Torque	650 in
Recommended in-lb	

Trade Name	SERVIT®
Plated	N
Sub Brand	SERVIT
UPC	781810014257
Type	KS
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810014257
UPC 14 Digit GTIN	00781810014257

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)

General



A Hubbell brand