




KS39, Split Bolt Connector, Run/Tap: 4/0 AWG Str-750 kcmil

By Burndy
Catalog # [KS39](#)

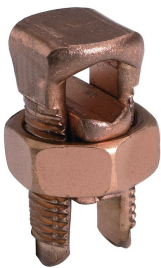

Copper Split Bolt, Cu: 4/0 AWG (Str)-750 kcmil (Run & Tap)

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Cables

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	• UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	• UL 486A • UL486B
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	4/0 STR - 750 KCMIL
Conductor - Copper Str Run	• 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil

Conductor - CopperWeld Str Tap Range	• 750 kcmil 19 #5
Conductor - CopperWeld Str Tap	19 #5
Conductor - CopperWeld Str Run Range	19 #5
Conductor - CopperWeld Str Run	19 #5
Conductor Type	• CU C Str-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Str-Tap
Conductor - Copper Str Tap Range	4/0 STR - 750 KCMIL
Conductor - Copper Str Tap	• 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	84 mm
Width	1.94 in
Dimension - Width mm	49 mm
Dimension - Width inch	1.94 in
Dimension - B Length inch	1.75 in
Dimension - Cross Flats inch	2.31 in
Dimension - Length Overall inch	3.51

Force Related

Installation Torque	1000 in	UPC 12 Digit	781810014752
Recommended in-lb		UPC 14 Digit GTIN	00781810014752
General		Logistics	
Trade Name	SERVIT®	Minimum Pack Quantity	1
Plated	N	Pallet Quantity	1
Sub Brand	SERVIT	Carton Quantity	1
UPC	781810014752	Product Assets	
Type	KS	Catalog [English]	
Material	Copper		
Plating Type	Unplated		



A Hubbell brand