




KS44, Split Bolt Connector, Run/Tap: 300-1000 kcmil

By Burndy
Catalog # [KS44](#)

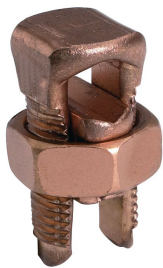

Copper Split Bolt, Cu: 300-1000 kcmil (Run & Tap)

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Cables

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	• UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	• UL 486A • UL486B
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	300 KCMIL - 1000 KCMIL
Conductor - Copper Str Run	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil • 800 kcmil

Conductor Type

- 850 kcmil
- 900 kcmil
- 1000 kcmil
- CU C Solid-Run
- CU C Str-Run
- CU Weld C Solid-Run
- CU Weld C Str-Run
- CU C Str-Tap
- CU Weld C Solid-Tap
- CU Weld C Str-Tap
- CU C Solid-Tap

Conductor - Copper Str Tap Range

Conductor - Copper Str Tap

300 KCMIL - 1000 KCMIL

- 4/0 AWG
- 250 kcmil
- 300 kcmil
- 350 kcmil
- 400 kcmil
- 450 kcmil
- 500 kcmil
- 550 kcmil
- 600 kcmil
- 700 kcmil
- 750 kcmil
- 800 kcmil
- 850 kcmil
- 900 kcmil
- 1000 kcmil

Configuration

Connector Type	Split Bolt
----------------	------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	95 mm
Width	2.19 in
Dimension - Width mm	56 mm
Dimension - Width inch	2.19 in
Dimension - B Length inch	2.10 in
Dimension - Cross Flats inch	2.56 in
Dimension - Length Overall inch	3.9

Force Related

Installation Torque 1100 in
Recommended in-lb

Plating Type Unplated
UPC 12 Digit 781810015001
UPC 14 Digit GTIN 00781810015001

General

Trade Name SERVIT®
Plated N
Sub Brand SERVIT
UPC 781810015001
Type KS
Material Copper

Logistics

Minimum Pack Quantity 1
Pallet Quantity 1
Carton Quantity 5

Product Assets

[Catalog \[English\]](#)



A Hubbell brand