



KSU17, Split Bolt Connector with Spacer, Tin Plated

By Burndy
Catalog # [KSU17](#)

Tin-plated, high strength copper alloy SERVIT with spacer. Spacer separates dissimilar conductors and provides long contact length

Features

- Tin-plated, high strength copper alloy with spacer
- Spacer separates dissimilar conductors and provides long contact length preventing high pressure point contacts between run and tap conductors

Application


For All Combinations Of Copper, Aluminum, ACSR, AAAC, 5005, And Steel

Specifications

EU RoHS Indicator	Yes
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Tap Range	30.58 (7) kcmil
Conductor - AAAC 5005 Tap	30.58 (7) kcmil
Conductor - AAAC 6201 Run Range	30.58 (7) kcmil
Conductor - AAAC 6201 Run	30.58 (7) kcmil
Conductor - Galvanized Steel Str Size	5/32 (7) in
Conductor - Galvanized Steel Str Size Range	5/32 (7) in
Conductor - AAAC 6201 Tap Range	30.58 (7) kcmil
Conductor - AAAC 6201 Tap	30.58 (7) kcmil
Conductor - AL Str Run Range	12 STR. 6 SOL.
Conductor - AL Str Run	• 8 AWG • 6 AWG
Conductor - AL Str Tap Range	12 STR. 6 SOL.
Conductor - AL Str Tap	• 8 AWG • 6 AWG
Conductor - ACSR Str Run Range	8 AWG
Conductor - ACSR Str Run	8 (6-1)
Conductor - ACSR Str Tap Range	8 AWG
Conductor - ACSR Str Tap	8 (6-1)

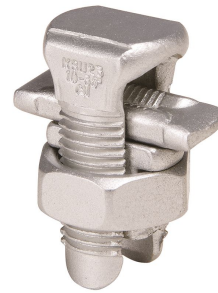

Conductor - Copper Str Run Range	12 STR. 6 SOL.
Conductor - Copper Str Run	• 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - Copper Solid Run Range	12 AWG-6 AWG
Conductor - Copper Solid Run	• 12 AWG • 11 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - Copper Solid Tap Range	12 AWG-6 AWG
Conductor - Copper Solid Tap	• 12 AWG • 11 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG
Conductor - AAAC 5005 Run Range	30.58 (7) kcmil
Conductor - AAAC 5005 Run	30.58 (7) kcmil
Conductor Type	• CU C Solid-Run • CU C Str-Run • AL C Str-Run • AAAC C 5005-Run • AAAC C 6201-Run • ACSR C Str-Run • CU C Solid-Tap • CU C Str-Tap • AL C Str-Tap • AAAC C 5005-Tap • AAAC C 6201-Tap • ACSR C Str-Tap • GAL Steel C Str-Size
Conductor - Copper Str Tap Range	12 STR. 6 SOL.
Conductor - Copper Str Tap	• 10 AWG

- 9 AWG
- 8 AWG
- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG

Configuration

Connector Type Split Bolt

Dimensions

Package Height 0.000 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimension - L Length Overall
mm 23 mm
Width 0.42 in
Dimension - Width mm 11 mm
Dimension - Width inch 0.42 in
Dimension - Cross Flats inch .62 in
Dimension - Length Overall
inch 1.14

Force Related

Installation Torque 165 LBS/in
Recommended in-lb

General

Trade Name SERVIT®
Plated Y
Sub Brand UNIVERSAL SERVIT
UPC 781810035009
Type KSU, Universal
Material Copper
Plating Type Tin Plated
UPC 12 Digit 781810035009
UPC 14 Digit GTIN 00781810035009

Logistics

Pallet Quantity 29700
Carton Quantity 100

Product Assets

[Catalog \[English\]](#)

