



KSU23, Split Bolt Connector with Spacer, Tin Plated

By Burndy
Catalog # [KSU23](#)

Tin-plated, high strength copper alloy SERVIT™ with spacer. Spacer separates dissimilar conductors and provides long contact length that prevents high pressure point contacts between run and tap conductors, 1.48 IN L.

Features

- Tin-plated, high strength copper alloy with spacer
- Spacer separates dissimilar conductors and provides long contact length preventing high pressure point contacts between run and tap conductors

Application


For All Combinations Of Copper, Aluminum, ACSR, AAAC, 5005, And Steel

Specifications

Standards - RoHS Compliance Status	CM
EU RoHS Indicator	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	8 AWG - 2 AWG
Conductor - AL Str Run Range	8 AWG - 2 AWG
Conductor - AL Str Tap Range	8 AWG - 2 AWG
Conductor - Copper Str Tap Range	8 AWG - 2 AWG
Conductor - ACSR Str Run Range	3 AWG - 2 AWG

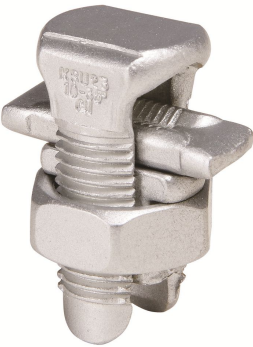

Conductor - ACSR Str Tap Range	6 AWG - 2 AWG
--------------------------------	---------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Width	0.59 in
Dimension - Length Overall	1.56 inch

General

Plated	Y
Trade Name	SERVIT®
Sub Brand	UNIVERSAL SERVIT
UPC	781810036006
Type	KSU, Universal
Material	Copper
Plating Type	Tin Plated

Logistics

Pallet Quantity	17400
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)