



KSU25GR, Split Bolt Connector with Spacer

By Burndy
Catalog # [KSU25GR](#)

Cu Alloy Universal SERVIT, Unplated-Conventional, #2 Str. Cu/Al, #3 AWG ACSR(Run), #10 Str. Cu/Al, #6 AWG ACSR(Tap)

Features


- Tin-plated, high strength copper alloy with spacer
- Spacer separates dissimilar conductors and provides long contact length preventing high pressure point contacts between run and tap conductors

Specifications

Standards - RoHS Compliance UI
Status

Conductor

Conductor Type	• CU C Solid-Run • CU C Str-Run • AL C Str-Run • AAAC C 5005-Run • AAAC C 6201-Run • ACSR C Str-Run • CU C Solid-Tap • CU C Str-Tap • AL C Str-Tap • AAAC C 5005-Tap
----------------	--

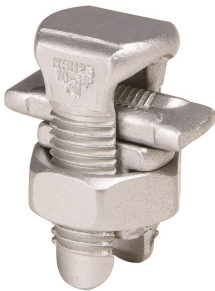

- AAAC C 6201-Tap
- ACSR C Str-Tap
- GAL Steel C Str-Size

Configuration

Connector Type	Split Bolt
----------------	------------

General

Trade Name	SERVIT®
Plated	Y
UPC 12 Digit	781810462393
UPC 14 Digit GTIN	00781810462393
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810462393

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalog \[English\]](#)



A Hubbell brand