




LF2027, Copper - Link Limiter, Pure Copper Link, LF, Amperage Rating: 250 AMP

By Burndy
Catalog # [LF2027](#)

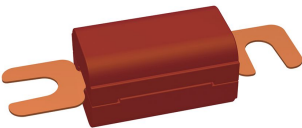

Pure Copper Link, LF, Amperage Rating: 250 AMP

Features

- Made of pure copper
- Limiter Link is controlled dimensionally to close tolerances to maintain accurate fusing characteristics
- Limiter Link is supplied enclosed in a shell with heatproof chamber to confine and break the arc created by fusing

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Configuration

Connector Type	Limiter
----------------	---------

Current

Amperage Rating	250 A
-----------------	-------

Dimensions

Dimension - Pad Width inch	3.06 in
Dimension - Width inch	1 in
Dimension - F Width Center to Center inch	0.42 in
Dimension - D inch	0.32 in
Dimension - Width fraction	1 in
Dimension - Length Overall inch	4.06 in

General

Plated	Y
UPC	781810000748
Material	Copper
Plating Type	Silver
UPC 12 Digit	781810000748
UPC 14 Digit GTIN	00781810000748

Logistics

Minimum Pack Quantity	100
Pallet Quantity	5568
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)