




Substation - Copper Terminal

By Burndy

Catalog # [NAH4444N](#)

Substation Connectors

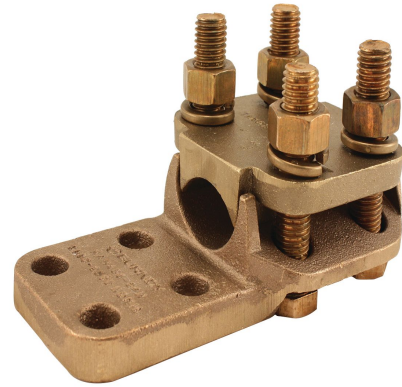

Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	EX
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	4/0 AWG 250 kcmil 300 kcmil 350 kcmil 400 kcmil 450 kcmil 500 kcmil 550 kcmil 600 kcmil 700 kcmil 750 kcmil 800 kcmil 850 kcmil 900 kcmil 1000 kcmil
Number Of Conductors	1
Conductor - Connection Combination	Cable to Flat
Conductor Type	- CU C Str-Size - CU C Solid-Size
Conductor - Copper Str Size Range	4/0 AWG-1000 kcmil

Configuration

Physical Attribute - Pad Orientation	Straight
Physical Attribute - Pad Configuration	4 x 4 - 4 holes
Physical Attribute - Pad Alignment	Offset
Physical Attribute - Number of Holes	4



A Hubbell brand

Connector Type

Terminal

Dimensions

Dimension - Pad Size inch	4 x 4
Dimension - Pad Width inch	4.00 in
Package Height	0.000 in
Dimension - Height mm	66.5 mm
Dimension - Hole Size fraction	9/16
Dimension - Height inch	2.62 in
Dimension - Height fraction	2-31/50 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.75 in
Package Width	0.000 in
Dimension - L Length Overall mm	181 mm
Dimension - Width fraction	2-22/25 in
Dimension - Hole Size inch	0.56 in
Dimension - B Length fraction	2-22/25 in
Dimension - Width mm	73 mm
Dimension - Width inch	2.88 in
Dimension - B Length inch	2.88 in
Dimension - D inch	4.00 in
Dimension - N inch	1.12 in
Dimension - Length Overall inch	7.12 in

General

Material - Hardware	DURIUM™ Silicon Bronze
One Wrench Installation	Y
Plated	N
Clamping Element Design	Body and Cap
UPC	781810053782
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810053782
UPC 14 Digit GTIN	00781810053782

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)