




Substation - Aluminum Bolted Terminal

By Burndy

Catalog # [NAR29A4N](#)

Cast Al Alloy Bolted Terminal, Al/Cu Cable To Flat, 1/0 Str - 250 kcmil Al/Cu, 1/0 - 4/0 AWG ACSR, 4-NEMA Pad Holes, .56" Hole Dia.

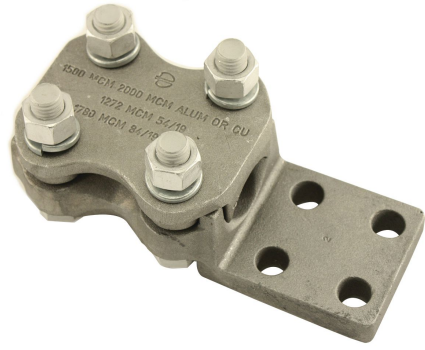

Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG 250 kcmil
Conductor - AL Str Size Range	1/0 AWG-250 kcmil
Conductor - ACSR Str Size	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Size Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Number Of Conductors	1
Conductor - Connection Combination	Cable to Flat
Conductor Type	- AL C Str-Size - ACSR C Str-Size

Configuration

Physical Attribute - Pad Orientation	Straight
Physical Attribute - Pad Configuration	3 x 3 - 4 holes
Physical Attribute - Pad Alignment	Offset
Physical Attribute - Number of Holes	4
Connector Type	Terminal

Dimensions

Dimension - Pad Width inch	3.00 in
Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Hole Size fraction	9/16
Dimension - Height inch	2.75 in
Dimension - Height fraction	2-3/4 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.75 in
Package Width	0.000 in
Dimension - L Length Overall mm	154 mm
Dimension - Thread Size	1/2
Dimension - Bolt Size fraction	1/2
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Dimension - B Length inch	2.88 in
Dimension - D inch	3.00 in
Dimension - N inch	0.63 in
Dimension - Length Overall inch	6.06 in

Force Related

Installation Torque	300 LBS/in
Recommended in-lb	

General

Material - Hardware	Aluminum
One Wrench Installation	Y
Plated	N
Clamping Element Design	Body And Cap
UPC	781810003800
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810003800
UPC 14 Digit GTIN	00781810003800

Logistics

Pallet Quantity	544
Carton Quantity	8

Product Assets

[Catalog \[English\]](#)

