




Substation - Aluminum Bolted Terminal

By Burndy
Catalog # [NAR29ACG7](#)

Substation Connectors

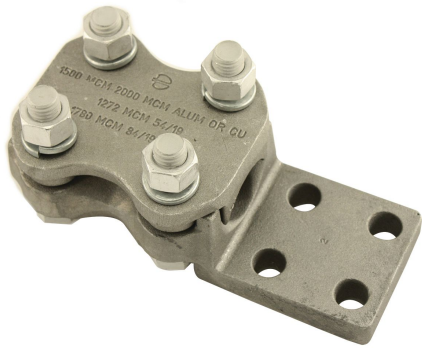

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Conductors	1
Conductor - Connection Combination	Cable to Flat
Conductor - AL Str Size	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG 250 kcmil
Conductor - AL Str Size Range	1/0 AWG-250 kcmil
Conductor Type	- AL C Str-Size - ACSR C Str-Size
Conductor - ACSR Str Size	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
Conductor - ACSR Str Size Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG

Configuration

Physical Attribute - Pad Orientation	Straight
Physical Attribute - Pad Alignment	Offset
Connector Type	Terminal

Dimensions

Dimension - Pad Width inch	1.62 in
Package Height	0.000 in
Dimension - Height mm	69.9 mm
Dimension - Height inch	2.75 in
Package Weight	0.000 lb.
Dimension - Width mm	63 mm
Dimension - Width inch	2.48 in
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.36 in
Package Width	0.000 in
Dimension - L Length Overall mm	155 mm
Dimension - B Length inch	1.62 in
Dimension - Length BB inch	2.88 in
Dimension - Length Overall inch	6.12 in

General

Plated	N
Material - Hardware	Aluminum
One Wrench Installation	Y
Clamping Element Design	Body And Cap
UPC	621945129047
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	621945129047
UPC 14 Digit GTIN	00621945129047

Logistics

Pallet Quantity	1080
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)