


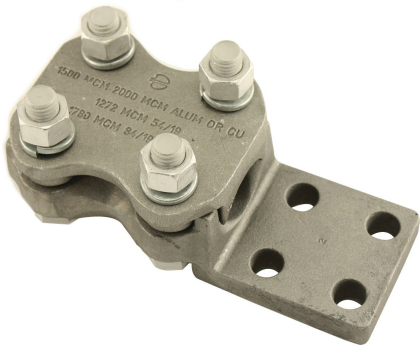

Application

Substation

Specifications

Standards - RoHS Compliance Status	EX
UL Listed	No

Conductor

Conductor - Connection Combination	Cable to Flat
Number Of Conductors	1
Conductor - ACSR Str Size	4/0 (6/1) Penguin AWG;80 (8/1) Grouse kcmil;101.8 (12/7) Petrel kcmil;110.8 (12/7) Minorca kcmil;134.6 (12/7) Leghorn kcmil;159 (12/7) Guinea kcmil;176.9 (12/7) Dotterel kcmil;190.8 (12/7) Dorking kcmil;211.3 (12/7) Cochin kcmil;203.2 (16/9) Brahma kcmil;266.8 (18/1) Waxwing kcmil;266.8 (26/7) Owl kcmil;266.8 (26/7) Partridge kcmil;300.0 (26/7) Ostrich kcmil;336.4 (18/1) Merlin kcmil;336.4 (26/7) Linnet kcmil;336.4 (30/7) Oriole kcmil;397.5 (18/1) Chickadee kcmil;397.5 (24/7) Brant kcmil;397.5 (26/7) Ibis kcmil;397.5 (30/7) Larkspur kcmil
Conductor Type	AL C Str-Size;ACSR C Str-Size
Conductor - ACSR Str Size Range	4/0 (6/1) Penguin AWG-397.5 (30/7) Larkspur kcmil
Conductor - AL Str Size	250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil
Conductor - AL Str Size Range	250 kcmil-400 kcmil

Configuration

Physical Attribute - Number of Holes	4
Physical Attribute - Pad Alignment	Offset
Physical Attribute - Pad Configuration	3 x 3 - 4 holes
Physical Attribute - Pad Orientation	45 Degree

Dimensions

Dimension - Width inch	3.00 in
Dimension - Width mm	76 mm
Dimension - F Width Center to Center inch	1.75 in
Dimension - Pad Width inch	3.00 in
Dimension - Height inch	2.88 in
Dimension - Height mm	73.2 mm
Dimension - Hole Size fraction	9/16
Dimension - D inch	3.00 in
Dimension - N inch	0.63 in

Force Related

Installation Torque Recommended in-lb	300 LBS/in
---------------------------------------	------------

General

Material - Hardware	Aluminum
UPC 12 Digit	781810167625
UPC 14 Digit GTIN	00781810167625
Material	Aluminum Alloy
One Wrench Installation	Y
Clamping Element Design	Body And Cap
UPC	781810167625

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalog \[English\]](#)