


Substation - Aluminum Bolted Terminal

By Burndy
Catalog # [NAR32A4N90](#)

Substation Connectors

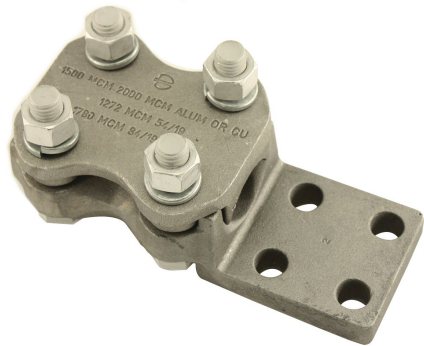

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	250 kcmil 266 kcmil 300 kcmil 336 kcmil 350 kcmil 397 kcmil 400 kcmil
Conductor - AL Str Size Range	250 kcmil-400 kcmil
Conductor Type	- AL C Str-Size - ACSR C Str-Size
Conductor - ACSR Str Size	4/0 (6/1) Penguin AWG 80 (8/1) Grouse kcmil 101.8 (12/7) Petrel kcmil 110.8 (12/7) Minorca kcmil 134.6 (12/7) Leghorn kcmil 159 (12/7) Guinea kcmil 176.9 (12/7) Dotterel kcmil 190.8 (12/7) Dorking kcmil 211.3 (12/7) Cochin kcmil 203.2 (16/9) Brahma kcmil 266.8 (18/1) Waxwing kcmil 266.8 (26/7) Owl kcmil 266.8 (26/7) Partridge kcmil 300.0 (26/7) Ostrich kcmil 336.4 (18/1) Merlin kcmil 336.4 (26/7) Linnet kcmil 336.4 (30/7) Oriole kcmil 397.5 (18/1) Chickadee kcmil 397.5 (24/7) Brant kcmil 397.5 (26/7) Ibis kcmil

Conductor - ACSR Str Size Range	397.5 (30/7) Larkspur kcmil 4/0 (6/1) Penguin AWG-397.5 (30/7) Larkspur kcmil
---------------------------------	--

Configuration

Physical Attribute - Pad Orientation	90 Degree
Connector Type	Terminal

Dimensions

Dimension - Pad Width inch	3.00 in
Package Height	0.000 in
Dimension - Height mm	151.6 mm
Dimension - Height inch	5.97 in
Package Weight	0.000 lb.
Dimension - Width mm	79 mm
Dimension - Width inch	3.12 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	87 mm
Dimension - B Length inch	3.00 in
Dimension - D inch	3.00 in
Dimension - N inch	0.62 in
Dimension - Length Overall inch	3.41 in

General

Plated	N
Material - Hardware	Aluminum
UPC	781810157367
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810157367
UPC 14 Digit GTIN	00781810157367

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)