


Substation - Connector

By Burndy
Catalog # [NBXR1544NHQ](#)

Copper Bus Connectors

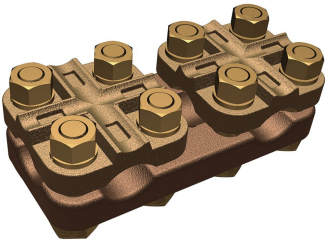

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	1/0 -1250 kcmil
Conductor - Copper Str Size	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil • 800 kcmil • 850 kcmil • 900 kcmil • 1000 kcmil • 1250 kcmil
Conductor - Copper Tube Std Size Range	1/4 IPS IPS-1 IPS IPS

Conductor - Copper Tube Std Size	• 1/4 IPS IPS • 3/8 IPS IPS • 1/2 IPS IPS • 3/4 IPS IPS • 1 IPS IPS
----------------------------------	---

Configuration

Connector Type	Terminal
----------------	----------

Dimensions

Dimension - Pad Width inch	4.00 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	183 mm
Dimension - B Length inch	2.88 in
Dimension - Length Overall inch	7.19 in

General

Plated	N
Material - Hardware	DURIUM™ Silicon Bronze
UPC	781810460276
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810460276
UPC 14 Digit GTIN	00781810460276

Logistics

Pallet Quantity	1
Carton Quantity	2

Product Assets

[Catalog \[English\]](#)