




Substation - Connector

By Burndy
Catalog # [NDR65534T0](#)

Copper Stud Connectors

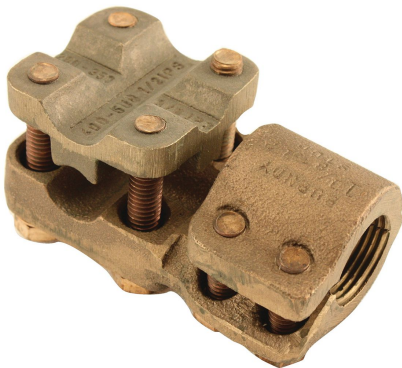

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	6 AWG 5 AWG 4 AWG 3 AWG 2 AWG 1 AWG 1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
Number Of Conductors	1
Conductor - Connection Combination	- Stud to Cable - Stud to Tube - Stud to Bar
Conductor - Copper Solid Size Range	6 AWG-4/0 AWG
Conductor - Copper Tube DEH Size Range	3/8 IPS -1/2 IPS
Conductor Type	- CU C Str-Size - CU Tube Std-Size - CU C Solid-Size
Conductor - Copper Tube DEH Size	3/8 IPS 1/2 IPS
Conductor - Copper Str Size Range	6 AWG-500 kcmil
Conductor - Copper Str Size	6 AWG 5 AWG 4 AWG 3 AWG 2 AWG 1 AWG 1/0

- 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil
 - 400 kcmil
 - 450 kcmil
 - 500 kcmil
- Conductor - Copper Tube Std Size Range
- Conductor - Copper Tube Std Size
- 3/8 IPS IPS
 - 1/2 IPS IPS
- Conductor - Copper Tube EH Size Range
- Conductor - Copper Tube EH Size
- 3/8 IPS IPS
 - 1/2 IPS IPS

Configuration

Connector Type	Stud Connector
----------------	----------------

Dimensions


Dimension - Pin Diameter inch	1.125 in
Dimension - Pin Diameter fraction	1-1/8 in
Package Height	0.000 in
Dimension - Height mm	56.9 mm
Dimension - Height inch	2.24 in
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - AA Pad Orientation	- In-line 90°
Package Width	0.000 in
Dimension - L Length Overall mm	101 mm
Dimension - B Length inch	1.53 in
Dimension - Length Overall inch	3.97 in

General

Plated	N
Material - Hardware UPC	DURIUM™ Silicon Bronze 621945457737
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	621945457737

Logistics

 Pallet Quantity1



Product Assets

[Catalog \[English\]](#)