


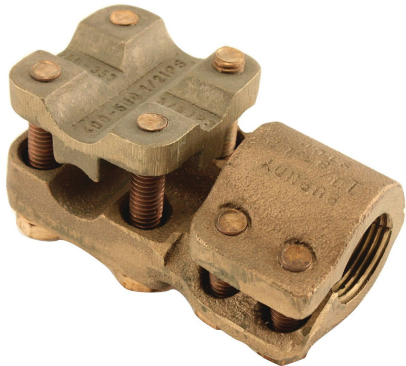

Substation - Connector

By Burndy
Catalog # [NDR6728T12](#)

High Cu Alloy Reversible & Rotatable Cap Stud Connector,
Bolted, #6 Sol - 4/0 Str Cu Cable, 1-1/2" - 12 Stud

Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	EX
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	6 AWG 5 AWG 4 AWG 3 AWG 2 AWG 1 AWG 1/0 2/0 AWG 3/0 AWG 4/0 AWG
-----------------------------	---

Conductor - Copper Solid Size	6 AWG 5 AWG 4 AWG 3 AWG 2 AWG 1 AWG 1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG
-------------------------------	---

Number Of Conductors	1
Conductor - Connection Combination	- Stud to Cable - Stud to Tube - Stud to Bar

Conductor - Copper Solid Size Range	6 AWG-4/0 AWG
-------------------------------------	---------------

Conductor Type	- CU C Str-Size - CU Tube Std-Size - CU C Solid-Size
----------------	--

Conductor - Copper Str Size Range	6 AWG-4/0 AWG
-----------------------------------	---------------

Configuration

Connector Type	Stud Connector
----------------	----------------

Dimensions

Dimension - Pin Diameter inch	1.5 in
Dimension - Pin Diameter fraction	1-1/2 in
Package Height	0.000 in
Dimension - Height mm	56.9 mm
Dimension - Height inch	2.24 in
Dimension - Height fraction	2-1/4 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	121 mm
Dimension - Threads per inch	12
Dimension - AA Pad Orientation	- In-line 90°
Dimension - B Length inch	2.09 in
Dimension - Length Overall inch	4.75 in

General

Material - Hardware Plated	DURIUM™ Silicon Bronze N
UPC	781810003534
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810003534
UPC 14 Digit GTIN	00781810003534

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)