



NHNT1634, Substation Copper T Connector, 90 Degrees, Tube to Cable, 1-1/4" IPS/EHPS Run, 1/0 AWG-500 kcmil Tap, 230kV

By Burndy
Catalog # [NHNT1634](#)

Substation T Connectors

Features

- Type NHNT for Copper Tube to Cable T Application
- High copper alloy reversible T-Connector for joining a wide range of run pipe and tap cables
- One-wrench installation

Application


Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance Status	EX
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Connection Combination	Tube to Cable
Conductor - Copper Solid Tap Range	2/0 AWG-4/0 AWG
Conductor - Copper Solid Tap	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor Type	• CU Tube Std-Run • CU C Str-Run • CU C Solid-Run • CU C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	1/0 -500 kcmil
Conductor - Copper Str Tap	• 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil

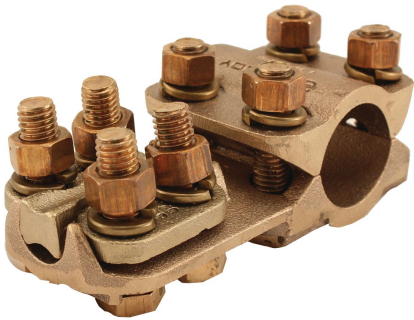

Conductor - Copper Tube Std Run Range	1 1/4 IPS
Conductor - Copper Tube Std Run	1 1/4 IPS

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	66 mm
Dimension - Height inch	2.60 in
Dimension - Height fraction	2-3/5 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	161 mm
Dimension - Width fraction	2-14/25 in
Dimension - B Length fraction	2-69/100 in
Dimension - Width mm	65 mm
Dimension - Width inch	2.56 in
Dimension - B Length inch	2.69 in
Dimension - Length BB inch	2.62 in
Dimension - Length Overall inch	6.32 in

Force Related


Installation Torque Recommended in-lb	480 lb-in
---------------------------------------	-----------

General

Material - Hardware	DURIUM™ Silicon Bronze
One Wrench Installation	Y
Plated	N
UPC	781810003114
Type	Tube to Cable Couplers
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810003114

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1

 

Product Assets

[Catalog \[English\]](#)