


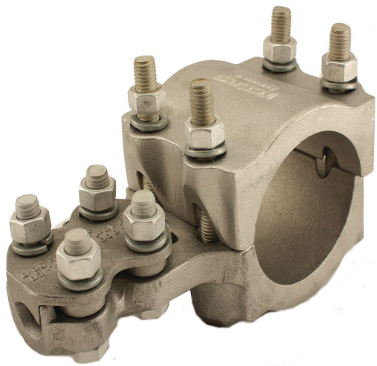

Substation - Connector

By Burndy
Catalog # [NNTR17A29A](#)

Cast Al Alloy Tee Connector, Tube to Cable, 1-1/2 IN IPS Al (Run),
1/0 AWG STR-250 KCMIL Al or Cu (Tap), 1/0-4/0 AWG ACSR
(Tap), 1/2 IN-13 Bolt Size



Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Tap Range	1/0 AWG-250 kcmil
Conductor - AL Str Tap	1/0 AWG 2/0 AWG 3/0 AWG 4/0 AWG 250 kcmil
Conductor - ACSR Str Tap Range	1/0 (6/1) Raven AWG-4/0 (6/1) Penguin AWG
Conductor - ACSR Str Tap	1/0 (6/1) Raven AWG 2/0 (6/1) Quail AWG 3/0 (6/1) Pigeon AWG 4/0 (6/1) Penguin AWG
Conductor - AL Tube Std Run Range	1 1/2 IPS
Conductor - AL Tube Std Run	1 1/2 IPS
Conductor - Connection Combination	Tube to Cable

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	96.8 mm
Dimension - Height inch	3.81 in
Dimension - Height fraction	3-7/8 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	170 mm
Dimension - Width mm	64 mm
Dimension - Width inch	2.50 in
Dimension - B Length inch	4 in
Dimension - Length BB inch	2.75 in
Dimension - Length Overall inch	6.69 in

Force Related

Installation Torque	300 LBS/in
Recommended in-lb	

General

Material - Hardware	Aluminum
One Wrench Installation	Y
Plated	N
UPC	781810004234
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810004234
UPC 14 Digit GTIN	00781810004234

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)