




Substation - Connector

By Burndy

Catalog # [NNTR22A45A](#)

Substation Connectors

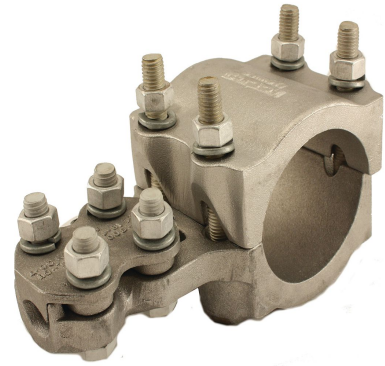

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Tube Std Run Range	4 IPS
Conductor - AL Tube Std Run	4 IPS
Conductor - Connection Combination	Tube to Cable
Conductor - AL Str Tap Range	900 kcmil-1250 kcmil
Conductor - AL Str Tap	900 kcmil 954 kcmil 1000 kcmil 1033 kcmil 1100 kcmil 1113 kcmil 1192 kcmil 1200 kcmil 1250 kcmil
Conductor - ACSR Str Tap Range	715.5 (54/7) Crow kcmil-1113 (54/19) Finch kcmil
Conductor - ACSR Str Tap	715.5 (54/7) Crow kcmil 715.5 (24/7) Stilt kcmil 715.5 (26/7) Starling kcmil 715.5 (30/19) Redwing kcmil 795 (54/7) Condor kcmil 795 (26/7) Drake kcmil 795 (30/19) Mallard kcmil 874.5 (54/7) Crane kcmil 900 (54/7) Canary kcmil 954 (45/7) Rail kcmil 954 (54/7) Cardinal kcmil 1033.5 (45/7) Ortolan kcmil 1033.5 (54/7) Curlew kcmil 1113 (54/19) Finch kcmil

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	146.1 mm
Dimension - Height inch	5.75 in
Package Weight	0.000 lb.
Dimension - Width mm	76 mm
Dimension - Width inch	3.00 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	264 mm
Dimension - B Length inch	4.00 in
Dimension - Length BB inch	3.75 in
Dimension - Length Overall inch	10.38 in

Force Related

Installation Torque	300 LBS/in
Recommended in-lb	

General

Plated	N
Material - Hardware	Aluminum
One Wrench Installation	Y
UPC	781810077085
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810077085
UPC 14 Digit GTIN	00781810077085

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)

