




Substation - Aluminum Bolted T Connector

By Burndy
Catalog # [NNTR32A32A](#)

Substation Connectors

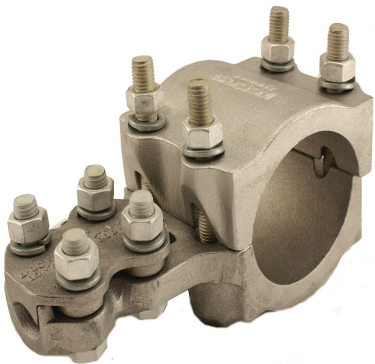

Features

- Aluminum alloy T-Connector for tubing run and tap
- Properly proportioned to permit use on copper-aluminum conductor combinations
- Captured hex head bolts permit one-wrench installation

Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	250 kcmil-400 kcmil
Conductor - AL Str Run	• 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil
Conductor - AL Str Tap Range	250 kcmil-400 kcmil
Conductor - AL Str Tap	• 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil • 397 kcmil • 400 kcmil
Conductor - ACSR Str Run Range	4/0 (6/1) Penguin AWG-397.5 (18/1) Chickadee kcmil
Conductor - ACSR Str Run	• 4/0 (6/1) Penguin AWG • 80 (8/1) Grouse kcmil • 101.8 (12/7) Petrel kcmil • 110.8 (12/7) Minorca kcmil • 134.6 (12/7) Leghorn kcmil • 159 (12/7) Guinea kcmil • 176.9 (12/7) Dotterel kcmil • 190.8 (12/7) Dorking kcmil

Conductor - ACSR Str Tap Range

Conductor - ACSR Str Tap

Conductor - Connection Combination

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	65 mm
Dimension - Height inch	2.56 in
Dimension - Height fraction	2-5/8
Package Weight	0.000 lb.

- 211.3 (12/7) Cochin kcmil
 - 203.2 (16/9) Brahma kcmil
 - 266.8 (18/1) Waxwing kcmil
 - 266.8 (26/7) Owl kcmil
 - 266.8 (26/7) Partridge kcmil
 - 300.0 (26/7) Ostrich kcmil
 - 336.4 (18/1) Merlin kcmil
 - 336.4 (26/7) Linnet kcmil
 - 336.4 (30/7) Oriole kcmil
 - 397.5 (18/1) Chickadee kcmil
 - 4/0 (6/1) Penguin AWG-397.5 (18/1) Chickadee kcmil
 - 4/0 (6/1) Penguin AWG
 - 80 (8/1) Grouse kcmil
 - 101.8 (12/7) Petrel kcmil
 - 110.8 (12/7) Minorca kcmil
 - 134.6 (12/7) Leghorn kcmil
 - 159 (12/7) Guinea kcmil
 - 176.9 (12/7) Dotterel kcmil
 - 190.8 (12/7) Dorking kcmil
 - 211.3 (12/7) Cochin kcmil
 - 203.2 (16/9) Brahma kcmil
 - 266.8 (18/1) Waxwing kcmil
 - 266.8 (26/7) Owl kcmil
 - 266.8 (26/7) Partridge kcmil
 - 300.0 (26/7) Ostrich kcmil
 - 336.4 (18/1) Merlin kcmil
 - 336.4 (26/7) Linnet kcmil
 - 336.4 (30/7) Oriole kcmil
 - 397.5 (18/1) Chickadee kcmil
- Cable to Cable

Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	151 mm
Dimension - B Length fraction	3 in
Dimension - Width mm	67 mm
Dimension - Width inch	2.63 in
Dimension - B Length inch	3.00 in
Dimension - Length BB inch	3.00 in
Dimension - Length Overall inch	5.94 in

Force Related

Installation Torque	300 LBS/in
Recommended in-lb	

General



A Hubbell brand

Material - Hardware	Aluminum
One Wrench Installation	Y
Plated	N
UPC	781810004241
Type	Bolted Tees
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810004241
UPC 14 Digit GTIN	00781810004241

Logistics

Minimum Pack Quantity	1
Pallet Quantity	108
Carton Quantity	3

Product Assets

[Catalog \[English\]](#)