




Substation - Aluminum Bolted T Connector

By Burndy
Catalog # [NNTR46A46A](#)

Substation Connectors

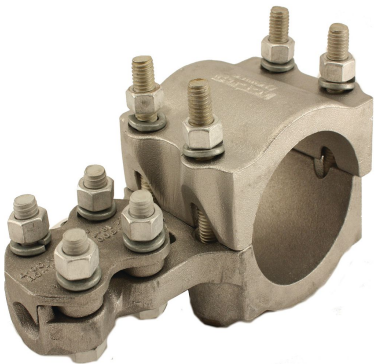

Features

- Aluminum alloy T-Connector for tubing run and tap
- Properly proportioned to permit use on copper-aluminum conductor combinations
- Captured hex head bolts permit one-wrench installation

Application

Substation

Specifications

Certification - UL Recognized	No
Certification - cULus	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Run Range	1250 kcmil-1600 kcmil
Conductor - AL Str Run	• 1250 kcmil • 1272 kcmil • 1300 kcmil • 1351 kcmil • 1400 kcmil • 1431 kcmil • 1500 kcmil • 1590 kcmil • 1600 kcmil
Conductor - AL Str Tap Range	1250 kcmil-1600 kcmil
Conductor - AL Str Tap	• 1250 kcmil • 1272 kcmil • 1300 kcmil • 1351 kcmil • 1400 kcmil • 1431 kcmil • 1500 kcmil • 1590 kcmil • 1600 kcmil
Conductor - ACSR Str Run Range	1113 (54/19) Finch kcmil-1431 (54/19) Plover kcmil
Conductor - ACSR Str Run	• 1113 (54/19) Finch kcmil • 1192.5 (45/7) Bunting kcmil • 1192.5 (54/19) Grackle kcmil • 1272 (54/19) Pheasant kcmil

Conductor - ACSR Str Tap Range
Conductor - ACSR Str Tap

Conductor - Connection Combination

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	93.7 mm
Dimension - Height inch	3.69 in
Dimension - Height fraction	3-3/4 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	211 mm
Dimension - B Length fraction	4-3/8 in
Dimension - Width mm	95 mm
Dimension - Width inch	3.75 in
Dimension - B Length inch	4.38 in
Dimension - Length BB inch	4.38 in
Dimension - Length Overall inch	8.31 in

Force Related

Installation Torque Recommended in-lb	480 LBS/in
---------------------------------------	------------

General

Material - Hardware	Aluminum
One Wrench Installation	Y

- 1351.5 (54/19) Martin kcmil
 - 1431 (54/19) Plover kcmil
 - 1113 (54/19) Finch kcmil-1431 (54/19) Plover kcmil
 - 1113 (54/19) Finch kcmil
 - 1192.5 (45/7) Bunting kcmil
 - 1192.5 (54/19) Grackle kcmil
 - 1272 (54/19) Pheasant kcmil
 - 1351.5 (54/19) Martin kcmil
 - 1431 (54/19) Plover kcmil
- Cable to Cable

Plated	N
UPC	781810004081
Type	Bolted Tees
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810004081
UPC 14 Digit GTIN	00781810004081

Logistics

Minimum Pack Quantity	6
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)



A Hubbell brand