




Substation - Connector

By Burndy
Catalog # [NNTR486A36A](#)

Substation Connectors

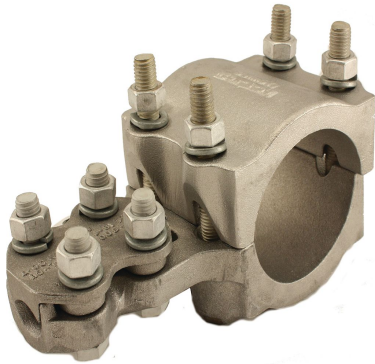

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Connection	Cable to Cable
Combination	
Conductor - AL Str Run Range	2000 kcmil-2500 kcmil
Conductor - AL Str Run	• 2000 kcmil • 2250 kcmil • 2300 kcmil • 2500 kcmil
Conductor - AL Str Tap Range	350 kcmil-600 kcmil
Conductor - AL Str Tap	• 350 kcmil • 397 kcmil • 400 kcmil • 450 kcmil • 477 kcmil • 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil
Conductor - ACSR Str Tap Range	336.4 (18/1) Merlin kcmil-477.0 (18/1) Pelican kcmil
Conductor - ACSR Str Tap	• 336.4 (18/1) Merlin kcmil • 336.4 (26/7) Linnet kcmil • 336.4 (30/7) Oriole kcmil • 397.5 (18/1) Chickadee kcmil • 397.5 (24/7) Brant kcmil • 397.5 (26/7) Ibis kcmil • 397.5 (30/7) Larkspur kcmil • 477.0 (18/1) Pelican kcmil

Configuration

Physical Attribute - Number of Tap Conductors	1
Physical Attribute - Number of Run Conductors	1
Connector Type	T-Connector

Dimensions

Package Height	0.000 in
Dimension - Height mm	98.6 mm
Dimension - Height inch	3.88 in
Package Weight	0.000 lb.
Dimension - Width mm	70 mm
Dimension - Width inch	2.75 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	193 mm
Dimension - B Length inch	3.75 in
Dimension - Length BB inch	3.25 in
Dimension - Length Overall inch	7.59 in

Force Related

Installation Torque	300 LBS/in
Recommended in-lb	

General

Plated	N
Material - Hardware	Aluminum
One Wrench Installation	Y
UPC	781810420034
Material	Aluminum Alloy
Plating Type	Unplated
UPC 12 Digit	781810420034
UPC 14 Digit GTIN	00781810420034

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)

