


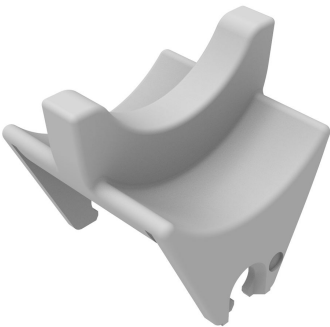

# Stainless Steel Holding P Die, 800 kcmil, Orange, Index 25

By Burndy  
Catalog # [P40RT](#)

15T P Die, 800 kcmil, Orange, Index 25



## Features

- Durable Stainless Steel Material
- Circumferential Crimp
- Twin P Style
- Color Code: Orange
- Die Index 25

## Application

Crimping

## Specifications

|                             |     |
|-----------------------------|-----|
| Standards - RoHS Compliance | EX  |
| Status                      |     |
| EU RoHS Indicator           | Yes |

## Dimensions

|                         |           |
|-------------------------|-----------|
| Package Height          | 0.000 in  |
| Package Weight          | 0.000 lb. |
| Package Length          | 0.000 in  |
| Package Width           | 0.000 in  |
| Weight                  | 0.80 lb.  |
| Dimension - Thread Size | -         |

## Force Related

|                      |        |
|----------------------|--------|
| Crimp Force Capacity | 15 ton |
|----------------------|--------|

## General

|                          |                                        |
|--------------------------|----------------------------------------|
| Application - For Use On | Use with Y46 and PAT46 Series Crimpers |
| Color Code               | Orange                                 |
| Die Index                | 25                                     |
| Die Type                 | P Die                                  |
| UPC                      | 781810627235                           |
| Type                     | Die                                    |
| UPC 12 Digit             | 781810627235                           |
| UPC 14 Digit GTIN        | 00781810627235                         |

## Logistics

|                       |          |
|-----------------------|----------|
| Minimum Pack Quantity | 1        |
| Package Contents      | Die only |
| Carton Quantity       | 1        |

## Product Assets

[Catalog \[English\]](#)