



Circular Non-Butting Twin Stainless Steel P Die, White, Index 27

By Burndy
Catalog # [P44RT](#)

15T P Die, Index 27

Features

- Durable Stainless Steel Material
- Circumferential Crimp
- Twin P Style
- Color Code: White
- Die Index 27

Application


Crimping

Specifications

Standards - RoHS Compliance Status	EX
EU RoHS Indicator	Yes

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Weight	0.64 lb.
Dimension - Thread Size	-

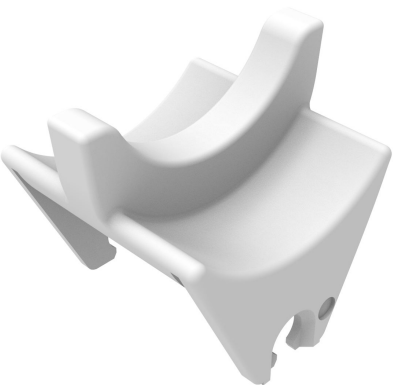

Force Related

Crimp Force Capacity	15 ton
----------------------	--------

General

Application - For Use On	Use with Y46 and PAT46 Series Crimpers
Color Code	Gold
Die Index	27
Die Type	P Die
UPC	781810009147
Type	Dies
UPC 12 Digit	781810009147
UPC 14 Digit GTIN	00781810009147

Logistics

Minimum Pack Quantity	1
Package Contents	Die only
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)