



PG1425X03D, Uninsulated Male/Female
Combination Quick Disconnect For 16 - 14
AWG (.25 x .03)

By Burndy
Catalog # PG1425X03D

Uninsulated Male/Female Combination Quick Disconnect For 16 -
14 AWG (.25 x .03)

Features

- Tin-Plated piggy-back connectors are designed to allow for additional terminals to be connected
- Sleeved barrel
- Funnel entry barrel opening assures quick and easy wire insertion
- Dimpled female socket detent assure firm grip

Specifications

Standards - RoHS Compliance CM
Status

Conductor


Conductor Size 16 - 14 AWG
Conductor Type • CU C Solid-Size
 • CU C Str-Size
Conductor Range #16 AWG to #14 AWG

Configuration

Connector Type Male/Female Quick Disconnect

Dimensions

Dimension - Width inch 0.25 in
Package Length 0.000 in

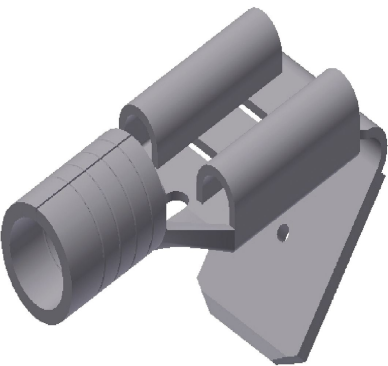

Dimension - Width mm 6 mm
Package Width 0.000 in
Package Weight 0.000 lb.
Dimension - B Length inch 0.17 in
Package Height 0.000 in
Dimension - Strip Length inch 3/8 in
Dimension - Length Overall 0.79 in
inch

General

Plated Y
Type Disconnect Connectors
UPC 12 Digit 781810530580
UPC 14 Digit GTIN 00781810530580
Material Brass
Plating Type Tin
UPC 781810530580

Logistics

Minimum Pack Quantity 100
Carton Quantity 1000
Pallet Quantity 1

Product Assets

[Catalog \[English\]](#)