



PG1825X03D, Uninsulated Male/Female  
Combination Quick Disconnect For 22 - 18  
AWG (.25 x .03)

By Burndy  
Catalog # PG1825X03D

Uninsulated Male/Female Combination Quick Disconnect For 22  
- 18 AWG (.25 x .03)

Features

- Tin-Plated piggy-back connectors are designed to allow for additional terminals to be connected
- Sleeved barrel
- Funnel entry barrel opening assures quick and easy wire insertion
- Dimpled female socket detent assure firm grip

Specifications

Standards - RoHS Compliance    UI  
Status


Conductor

Conductor Size                    22 - 18 AWG  
Conductor Type                    • CU C Solid-Size  
                                              • CU C Str-Size  
Conductor Range                    #22 AWG to #18 AWG

Configuration

Connector Type                    Male/Female Quick Disconnect

Dimensions

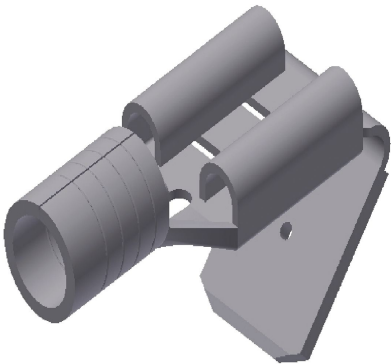

Dimension - Width inch            0.25 in  
Dimension - Width mm            6 mm  
Dimension - B Length inch        0.17 in  
Dimension - Strip Length inch    3/8 in  
Dimension - Length Overall       0.79 in  
inch

General

Plated                                    Y  
Type                                    Disconnect Connectors  
UPC 12 Digit                        781810530597  
UPC 14 Digit GTIN                00781810530597  
Material                                Brass  
Plating Type                         Tin  
UPC                                    781810530597

Logistics

Minimum Pack Quantity            100

Product Assets

[Catalog \[English\]](#)