



PGHS1425X03D, Heat Shrink Male/Female Combination Quick Disconnect For 16 - 14 AWG (.25 x .03)

By Burndy
Catalog # [PGHS1425X03D](#)

Heat Shrink Male/Female Combination Quick Disconnect For 16 - 14 AWG (.25 x .03)

Features

- Tin-Plated piggy-back connectors are designed to allow for additional terminals to be connected
- Sleeved barrel
- Funnel entry barrel opening assures quick and easy wire insertion
- Dimpled female socket detent assure firm grip

Application


For Use on Copper Conductor

Specifications

Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

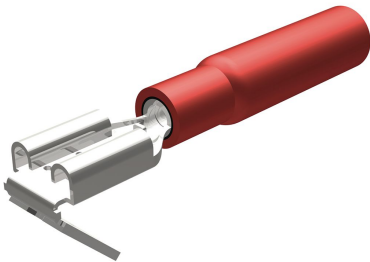

Configuration

Connector Type	Male/Female Quick Disconnect
----------------	------------------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - B Length inch	0.17 in
Package Height	0.000 in
Dimension - Strip Length inch	5/16 in

General

Sub Brand	HYDENT
Insulation Type	Heat Shrink
Type	Electrical Terminal
UPC 12 Digit	781810524077
UPC 14 Digit GTIN	00781810524077
Material	Brass
UPC	781810524077

Logistics

Minimum Pack Quantity	100
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)