




QN14M18X02B, Nylon Male Quick Disconnect For 16 - 14 AWG (.19 x .02)

By Burndy
Catalog # [QN14M18X02B](#)

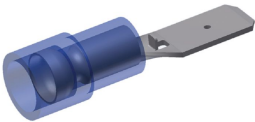

Nylon Male Quick Disconnect For 16 - 14 AWG (.19 x .02)

Features

- Sleeved barrel
- Funnel entry barrel opening assures quick and easy wire insertion
- Mates with dimpled female socket detent ensuring firm grip

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#16 AWG to #14 AWG

Configuration

Connector Type	Male Quick Disconnect
----------------	-----------------------

Current

Voltage - Maximum	300 V
-------------------	-------

Dimensions

Dimension - Width inch	0.187 in
Dimension - Width mm	5 mm
Dimension - Strip Length inch	3/8 in
Dimension - Length Overall inch	0.8 in

General

Insulation Type	Nylon
Trade Name	FINGRIP™
Plated	Y
Insulation	Y
Type	Disconnect Connectors
UPC 12 Digit	781810292839
UPC 14 Digit GTIN	00781810292839
Material	Brass
Plating Type	Tin
UPC	781810292839

Logistics

Minimum Pack Quantity	1000
Carton Quantity	1000
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)