



QN18M18X02B, Nylon Male Quick Disconnect For 22 - 18 AWG (.19 x .02)

By Burndy
Catalog # [QN18M18X02B](#)

Nylon Male Quick Disconnect For 22 - 18 AWG (.19 x .02)

Features

- Sleeved barrel
- Funnel entry barrel opening assures quick and easy wire insertion
- Mates with dimpled female socket detent ensuring firm grip

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor


Conductor Size	22 - 18 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#22 AWG to #16 AWG

Configuration

Connector Type	Male Quick Disconnect
----------------	-----------------------

Current

Voltage - Maximum	300 V
-------------------	-------

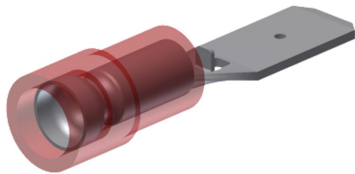

Dimensions

Dimension - Width mm	5 mm
Dimension - Width inch	0.187 in
Dimension - Length Overall inch	0.8 in
Dimension - Strip Length inch	3/8 in

General

Plated	Y
Insulation Type	Nylon
Trade Name	FINGRIP™
UPC	781810327593
Type	Disconnect Connectors
Insulation	Y
Material	Brass
Plating Type	Tin
UPC 12 Digit	781810327593
UPC 14 Digit GTIN	00781810327593

Logistics

Pallet Quantity	99999
Carton Quantity	1000

Product Assets

[Catalog \[English\]](#)