


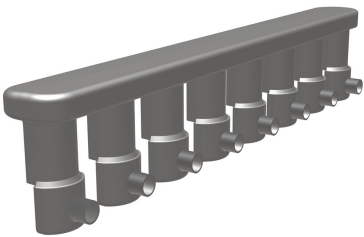

RDM728T, URD Mole 7 outlets total

By Burndy
Catalog # [RDM728T](#)

URD MOLE, #12 Sol - 350 kcmil(6 Outlets) & 350 - 500 kcmil(1 Outlet)



Features

- Type RDM-28 MOLE connectors are economical, insulated, submersible service junction suitable for direct burials or for use in enclosures
- Disconnectable Joints allow additions of new services without disturbing previous installations
- Taping is eliminated, Heat Shrink or Force-Fit Rubber Sleeves insulate each joint
- Rubber is used to insulated the MOLE body
- Removable sealing covers are supplied on all outlets but two
- REA Listed Tap Kits, including HYLUG, Hardware and Sleeve are ordered separately

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	4 AWG-4/0 AWG
Conductor - Copper Str Run	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - AL Str Run Range	4 AWG-350 kcmil
Conductor - AL Str Run	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG

- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 266 kcmil
- 300 kcmil
- 336 kcmil
- 350 kcmil

Conductor - Copper Str Tap Range	500 kcmil
Conductor - Copper Str Tap	500 kcmil

Configuration

Number Of Outlets	7
Connector Type	Mole

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Length Overall	11.53 in

General

Plated	Y
Insulation Type	Vinyl
Trade Name	MOLE™
UPC	781810180204
Insulation	Y
Material	Aluminum Alloy
Plating Type	Tin
UPC 12 Digit	781810180204
UPC 14 Digit GTIN	00781810180204

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalog \[English\]](#)