


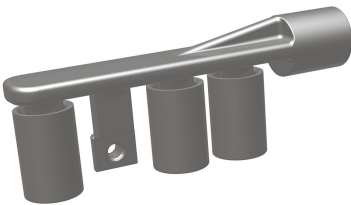

RDMD42858D, Aluminum - Multiple Outlet Connector For Transformers (RDM Mole)



By Burndy
Catalog # [RDMD42858D](#)

Insulated URD Stud Mole with Al Alloy Adaptor, 4 Outlets, #4 Str
- 250 kcmil Al/Cu, 300 - 350 kcmil Al

Features

- Insulated Connector - up to 600V
- Submersible

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 266 kcmil • 300 kcmil • 336 kcmil • 350 kcmil
Conductor - AL Str Size Range	4 AWG-350 kcmil
Conductor - Copper Str Size Range	4 AWG-250 kcmil
Conductor - Copper Str Size	• 4 AWG • 3 AWG

- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil

Configuration

Connector Type	Stud Connector
----------------	----------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Insulation Type	Rubber
Trade Name	MOLE™
UPC	781810180501
Insulation	Y
UPC 14 Digit GTIN	00781810180501

Logistics

Minimum Pack Quantity	12
Pallet Quantity	1080
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)



A Hubbell brand