


S1300, CPI Automatic Splice Connector

By Burndy
Catalog # [S1300](#)

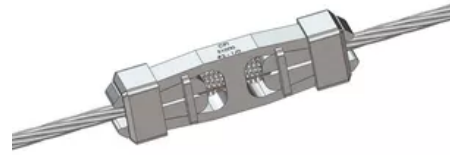

Conductor range: 3/0 ACSR, AAC, AAAC Reduce to 1/0 ACSR, AAC, AAAC

Features

- Only automatic splice available where you can see that the wire is fully inserted and installed properly
- No need to mark and measure the depth of cable insertion
- Open design helps prevent corrosion by allowing water and contamination to drain
- Stainless steel springs resist corrosion
- Tested to ANSI C119.4 specification*
- Minimum 5% tension needed to maintain electrical connection
- Positive center stop for conductor
- Minimal distance lost when sagging conductor
- Chamfered wedge aids cable insertion
- 4:1 surface area vs. cable for optimal conductivity

- Slider handle allows the splice to be released if needed
- Individually packaged in sealed plastic bags to prevent contamination before use

General

Catalog Number	S1300
UPC	621945684737

Product Assets

[Installation Manuals - Automatic Splice Connectors](#)

[Specifications - S1300](#)

[Video - CPI Automatic Splice](#)



A Hubbell brand