




S1500, CPI Automatic Splice Connector

By Burndy
Catalog # [S1500](#)

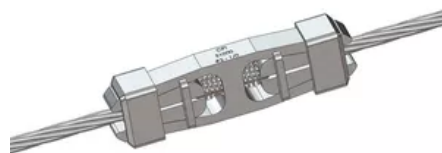

Conductor range: 2/0 (0.414" - 0.447")

Features

- Only automatic splice available where you can see that the wire is fully inserted and installed properly
- No need to mark and measure the depth of cable insertion
- Open design helps prevent corrosion by allowing water and contamination to drain
- Stainless steel springs resist corrosion
- Tested to ANSI C119.4 specification*
- Minimum 5% tension needed to maintain electrical connection
- Positive center stop for conductor
- Minimal distance lost when sagging conductor
- Chamfered wedge aids cable insertion
- 4:1 surface area vs. cable for optimal conductivity
- Slider handle allows the splice to be released if needed
- Individually packaged in sealed plastic bags to prevent contamination before use

General

Catalog Number	S1500
UPC	621945684751

Conductor Related

Conductor Range	Main Conductor: 2/0 (.414" - .447")
-----------------	-------------------------------------

Product Assets

[Catalogs - BURNDY Master Catalog - Section J - OH Distribution / Transmission](#)

[Installation Manuals - Automatic Splice Connectors](#)

[Specifications - S1500](#)

[Video - CPI Automatic Splice](#)



A Hubbell brand

©2025 Hubbell Incorporated. All rights reserved
BRDY-S1500-SPEC-EN | REV 7/2025