


Substation - Aluminum Rigid Spacer

By Burndy
Catalog # [SH2GBP41A512](#)

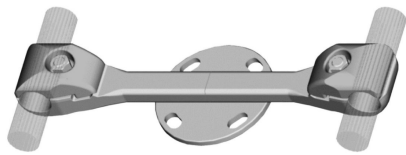

Cast Aluminum Bus Support 12 IN Spacer, 795 kcmil-874.5 kcmil
AAC, 795 kcmil (45/7) ACSR

Features

- Aluminum alloy streamlined rigid spacer for range of cables with bus support mounting base
- 2 bolts per clamping module
- EHV Rated: Self-Shielding up to 550kV

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Conductors	2
Conductor - Connection Combination	Base to Cable
Conductor - AL Str Size	• 795 kcmil • 800 kcmil • 874 kcmil
Conductor - AL Str Size Range	795 kcmil-874 kcmil
Conductor - ACSR Str Size	795 (54/7) Condor kcmil
Conductor - ACSR Str Size Range	795 (54/7) Condor kcmil

Configuration

Connector Type	Bus Support Spacer
----------------	--------------------

Dimensions

Bolt Circle Diameter	5.00 in
Dimension - G inch	1.50 in
Package Height	0.000 in
Dimension - Height mm	72.4 mm
Dimension - Height inch	2.85 in
Package Weight	0.000 lb.
Dimension - Width mm	159 mm
Dimension - Width inch	6.25 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	348 mm
Dimension - B Length inch	3.00 in
Dimension - Length Overall inch	13.71 in

General

Plated	N
UPC	781810234143
Material	Aluminum Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810234143
UPC 14 Digit GTIN	00781810234143

Logistics

Minimum Pack Quantity	9
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)