


Substation - Aluminum Rigid Spacer

By Burndy

Catalog # [SH2GBP46A512](#)

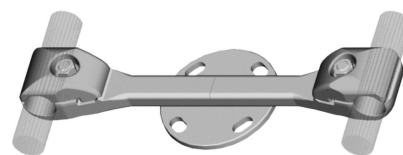

Cast Aluminum Bus Support 12 IN Spacer, 1590 kcmil-1600 kcmil
AAC, 1272 (54/19) kcmil -1431 (54/19) kcmil ACSR

Application

Substation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Conductors	2
Conductor - Connection Combination	Base to Cable
Conductor - AL Str Size	1590 kcmil 1600 kcmil
Conductor - AL Str Size Range	1590 kcmil-1600 kcmil
Conductor - ACSR Str Size	1272 (54/19) Pheasant 1431 (54/19) Plover
Conductor Spacing	12 in
Conductor - ACSR Str Size Range	1272 (54/19) Pheasant-1431 (54/19) Plover

Configuration

Physical Attribute - Number of Clamping Elements	1
Connector Type	Bus Support Spacer

Dimensions

Bolt Circle Diameter	5.00 in
Dimension - G inch	1.50 in
Dimension - Height mm	73.2 mm

Dimension - Hole Size fraction	11/16
Dimension - Height inch	2.88 in
Dimension - Width mm	159 mm
Dimension - Width inch	6.25 in
Dimension - L Length Overall mm	305 mm
Dimension - B Length inch	3.00 in
Dimension - Diameter Min Size inch	1.328 in
Dimension - Diameter Max Size inch	1.504 in
Dimension - Hole Size inch	0.69 in
Dimension - Length Overall inch	12.00 in

General

Plated	N
Material - Hardware	Aluminum Alloy
Fitting Type	Slip or Rigid
One Wrench Installation	Y
UPC	781810257531
Mounting Hardware	5/8-11 x 1" GS
Material	Aluminum Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810257531
Hardware Type	Cap mounting kit (w/o nuts)
UPC 14 Digit GTIN	00781810257531

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)