

Substation - Aluminum Rigid Spacer

By Burndy
Catalog # SH2GBP48A5

Cast Aluminum Bus Support 12 IN Spacer, 1750 kcmil-2000 kcmil
AAC, 1590 (45/7) kcmil -1780 (84/19) kcmil ACSR

Features

- Aluminum alloy streamlined rigid spacer for range of cables with bus support mounting base
- 2 bolts per clamping module
- EHV Rated: Self-Shielding up to 550kV

Application

Substation

Specifications


Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Number Of Conductors	2
Conductor - Connection Combination	Base to Cable
Conductor - AL Str Size	1750 kcmil 1800 kcmil 1900 kcmil 2000 kcmil
Conductor - AL Str Size Range	1750 kcmil-2000 kcmil
Conductor - ACSR Str Size	1590 (45/7) Lapwing kcmil 1590 (54/19) Falcon kcmil 1780 (54/19) kcmil 1780 (84/19) Chukar kcmil
Conductor Spacing	18 in
Conductor - ACSR Str Size Range	1590 (45/7) Lapwing kcmil-1780 (84/19) Chukar kcmil

Configuration

Physical Attribute - Number of Clamping Elements	1
--	---

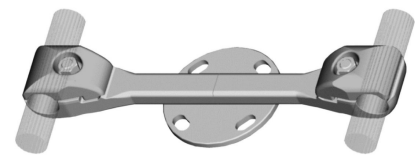

Connector Type	Bus Support Spacer
----------------	--------------------

Dimensions

Bolt Circle Diameter	5.00 in
Dimension - G inch	1.50 in
Dimension - Height mm	65 mm
Dimension - Hole Size fraction	11/16
Dimension - Height inch	2.56 in
Dimension - Width mm	159 mm
Dimension - Width inch	6.25 in
Dimension - L Length Overall mm	457 mm
Dimension - B Length inch	3.00 in
Dimension - Diameter Min Size inch	1.504 in
Dimension - Diameter Max Size inch	1.632 in
Dimension - Hole Size inch	0.69 in
Dimension - Length Overall inch	18.00 in

General

Plated	N
Material - Hardware	Aluminum Alloy
Fitting Type	Slip or Rigid
One Wrench Installation	Y
UPC	781810282274
Mounting Hardware	5/8-11 x 1" GS
Material	Aluminum Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810282274
Hardware Type	Cap mounting kit (w/o nuts)
UPC 14 Digit GTIN	00781810282274

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalog \[English\]](#)