




T1010BF, Uninsulated Block Fork Terminal For 12 - 10 AWG

By Burndy
Catalog # [T1010BF](#)

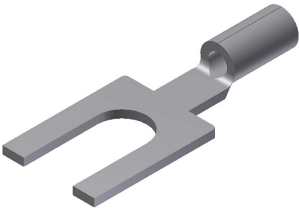

Uninsulated Block Fork Terminal For 12 - 10 AWG

Features

- Permits rapid, easy installation of the terminal under the screw head without complete removal of the screw
- Designed to fit securely into terminal blocks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Block Fork Terminal
----------------	---------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Z inch	0.85 in
Dimension - L Length Overall mm	23 mm

Dimension - Pad Width inch	0.35 in
Package Height	0.000 in
Dimension - Bolt Size fraction	#8 - #10
Dimension - Strip Length inch	11/32
Dimension - Stud Size inch	• #8 • #9 • #10
Dimension - Length Overall inch	0.90 in

General

Physical Attribute - Tongue Type	Fork
Trade Name	HYDENT™
Plated	Y
Feature - Barrel Style	Shrouded
Type	Fork Tongue
UPC 12 Digit	781810530696
UPC 14 Digit GTIN	00781810530696
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810530696

Logistics

Minimum Pack Quantity	100
Carton Quantity	1
Pallet Quantity	1

Product Assets

[Catalog \[English\]](#)