




T1010LF, Uninsulated Locking Fork Terminal For 12 - 10 AWG

By Burndy
Catalog # [T1010LF](#)

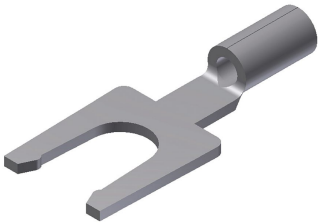

Uninsulated Locking Fork Terminal For 12 - 10 AWG

Features

- Locking Fork Tongue design
- Allows for fast installation, screw only has to be loosened for termination
- Internal configuration of the fork prevents the terminal from coming off the screw without applying a pulling force
- Locking fork is made from copper alloy, permits many installation while maintaining proper spring retention of forks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	UI
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Locking Fork Terminal
----------------	-----------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Z inch	0.29 in

Dimension - L Length Overall mm	23 mm
Dimension - Pad Width inch	0.35 in
Package Height	0.000 in
Dimension - Bolt Size fraction	#8 - #10
Dimension - Strip Length inch	11/32
Dimension - Stud Size inch	• #8 • #9 • #10
Dimension - Length Overall inch	0.90 in

General

Physical Attribute - Tongue Type	Fork
Trade Name	HYLUG™
Plated	Y
Feature - Barrel Style	Shrouded
UPC 12 Digit	781810530702
UPC 14 Digit GTIN	00781810530702
Material	Copper
Plating Type	Unplated
UPC	781810530702

Logistics

Minimum Pack Quantity	100
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)