




T106BF, Uninsulated Block Fork Terminal For 12 - 10 AWG

By Burndy
Catalog # [T106BF](#)

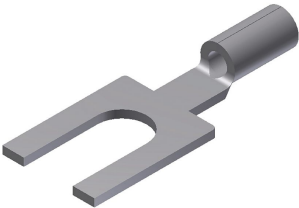

Uninsulated Block Fork Terminal For 12 - 10 AWG

Features

- Permits rapid, easy installation of the terminal under the screw head without complete removal of the screw
- Designed to fit securely into terminal blocks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Block Fork Terminal
----------------	---------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Z inch	0.87 in
Dimension - L Length Overall	23 mm
mm	

Dimension - Pad Width inch	0.30 in
Package Height	0.000 in
Dimension - Bolt Size fraction	#4 - #6
Dimension - Strip Length inch	11/32
Dimension - Stud Size inch	• #4 • #5 • #6
Dimension - Length Overall	0.90 in
inch	

General

Physical Attribute - Tongue	Fork
Type	
Trade Name	HYDENT™
Plated	Y
Feature - Barrel Style	Shrouded
Type	Fork Tongue
UPC 12 Digit	781810530719
UPC 14 Digit GTIN	00781810530719
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810530719

Logistics

Minimum Pack Quantity	100
Carton Quantity	1
Pallet Quantity	1

Product Assets

[Catalog \[English\]](#)