




T148BF, Uninsulated Block Fork Terminal For 16 - 14 AWG

By Burndy
Catalog # [T148BF](#)

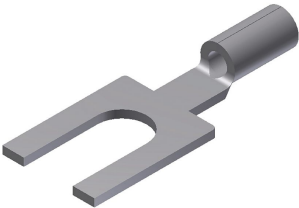

Uninsulated Block Fork Terminal For 16 - 14 AWG

Features

- Permits rapid, easy installation of the terminal under the screw head without complete removal of the screw
- Designed to fit securely into terminal blocks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Configuration

Connector Type	Block Fork Terminal
----------------	---------------------

Dimensions

Dimension - Z inch	0.80 in
Dimension - L Length Overall mm	21 mm
Dimension - Pad Width inch	0.30 in

Dimension - Bolt Size fraction	#6 - #8
Dimension - Strip Length inch	9/32
Dimension - Stud Size inch	• #6 • #8
Dimension - Length Overall inch	0.83 in

General

Physical Attribute - Tongue Type	Fork
Trade Name	HYDENT™
Plated	Y
Feature - Barrel Style	Shrouded
Type	Fork Tongue
UPC 12 Digit	781810530801
UPC 14 Digit GTIN	00781810530801
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810530801

Logistics

Minimum Pack Quantity	100
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)