




T148LF, Uninsulated Locking Fork Terminal For 16 - 14 AWG

By Burndy
Catalog # [T148LF](#)

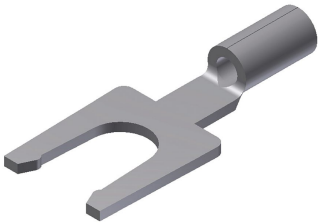

Uninsulated Locking Fork Terminal For 16 - 14 AWG

Features

- Locking Fork Tongue design
- Allows for fast installation, screw only has to be loosened for termination
- Internal configuration of the fork prevents the terminal from coming off the screw without applying a pulling force
- Locking fork is made from copper alloy, permits many installation while maintaining proper spring retention of forks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#16 AWG to #14 AWG

Configuration

Connector Type	Locking Fork Terminal
----------------	-----------------------

Dimensions

Package Length	0.000 in
----------------	----------

Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Z inch	0.30 in
Dimension - L Length Overall mm	21
Dimension - Pad Width inch	0.30 in
Package Height	0.000 in
Dimension - Bolt Size fraction	#6 - #8
Dimension - Strip Length inch	9/32 in
Dimension - Stud Size inch	#6 - #8
Dimension - Length Overall inch	0.83 in

General

Physical Attribute - Tongue Type	Snap Fork
Trade Name	HYLUG™
Feature - Barrel Style	Shrouded
UPC 12 Digit	781810530795
UPC 14 Digit GTIN	00781810530795
Material	Copper
UPC	781810530795

Logistics

Minimum Pack Quantity	100
Carton Quantity	100
Pallet Quantity	6000

Product Assets

[Catalog \[English\]](#)