




T166BF, Uninsulated Block Fork Terminal For 22 - 16 AWG

By Burndy
Catalog # [T166BF](#)

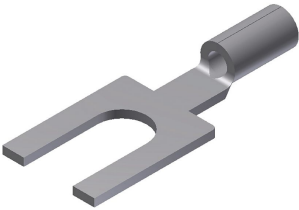

Uninsulated Block Fork Terminal For 22 - 16 AWG

Features

- Permits rapid, easy installation of the terminal under the screw head without complete removal of the screw
- Designed to fit securely into terminal blocks

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	22 - 16 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#22 AWG to #18 AWG

Configuration

Connector Type	Block Fork Terminal
----------------	---------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - Z inch	0.32 in

Dimension - L Length Overall	21 mm
Dimension - Pad Width inch	0.25 in
Package Height	0.000 in
Dimension - Bolt Size fraction	#4 - #6
Dimension - Strip Length inch	9/32 in
Dimension - Stud Size inch	#4 - #6
Dimension - Length Overall	0.83 in
inch	

General

Physical Attribute - Tongue	Block Fork
Type	
Trade Name	HYDENT™
Plated	Y
Feature - Barrel Style	Shrouded
Type	Fork Tongue
UPC 12 Digit	781810530849
UPC 14 Digit GTIN	00781810530849
Material	Copper
Plating Type	Tin
UPC	781810530849

Logistics

Minimum Pack Quantity	100
Carton Quantity	1
Pallet Quantity	1

Product Assets

[Catalog \[English\]](#)