


TN1010LF, Nylon Locking Fork Terminal For 12 - 10 AWG

By Burndy
Catalog # [TN1010LF](#)

Nylon Locking Fork Terminal For 12 - 10 AWG

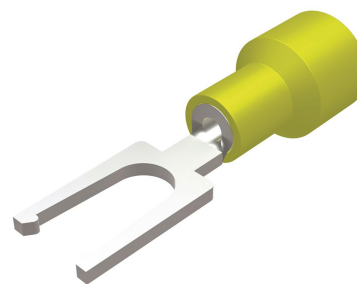

Features

- Locking fork tongue design allows fast installation, screw only has to be loosened for termination
- Internal configuration of the fork prevents the terminal from coming off the screw without applying a pulling force
- Locking fork is made from copper alloy, permits many installations while maintaining proper spring retention of forks

Application

Power Connector

Specifications

Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No
Buy America(n) Qualified	Contact Manufacturer

Conductor

Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#12 AWG to #10 AWG

Configuration

Connector Type	Locking Fork Terminal
----------------	-----------------------

Dimensions

Package Length	4.000 in
Package Width	3.000 in

Package Weight	0.225 lb.
Dimension - Z inch	0.29 in
Dimension - L Length Overall mm	26 mm
Dimension - Pad Width inch	0.35 in
Package Height	1.500 in
Dimension - Bolt Size fraction	#8 - #10
Dimension - Strip Length inch	11/32 in
Dimension - Stud Size inch	#8 - #10
Cable Insulation Diameter Maximum	0.26 in
Dimension - Length Overall inch	1.02 in

General

Sub Brand	HYDENT
Insulation Type	Nylon
Physical Attribute - Tongue Type	Snap Fork
Trade Name	INSULUG™
Plated	Y
Insulation Type	TN
UPC 12 Digit	781810524107
UPC 14 Digit GTIN	00781810524107
Material	Copper
Plating Type	Tin - Electro Plated
UPC	781810524107

Logistics

Minimum Pack Quantity	1
Carton Quantity	100
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)