




UC25A12SLS1, Parallel Tap, Aluminum Clamp

By Burndy
Catalog # [UC25A12SLS1](#)

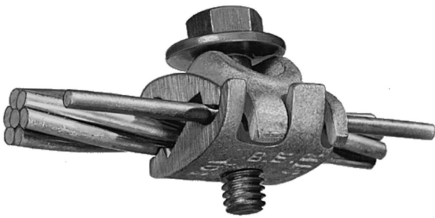

Aluminum Clamp, Parallel Tap, 1/0 (Str.) AWG AL to 12 AWG CU

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AL Str Size	1/0 AWG
Conductor - Copper Str Size	12 AWG

Dimensions

Length	1.3 in
Dimension - Width mm	22 mm
Dimension - Width inch	0.88 in
Height	1 in
Width	0.88 in
Dimensions	1.3 in x 0.88 in x 1 in

Force Related

Installation Torque	140 in-lb
Recommended in-lb	

General

Plated	N
UPC	781810084991
Material	Aluminum
Plating Type	Unplated
UPC 12 Digit	781810084991
UPC 14 Digit GTIN	00781810084991

Logistics

Minimum Pack Quantity	1
Pallet Quantity	7400
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)