




UC2834, Copper Parallel Groove Clamp

By Burndy
Catalog # UC2834

CU Parallel Groove Clamp accommodates large number of CU Conductors, Conductor: 4/0 Str. - 500 (Either Groove)

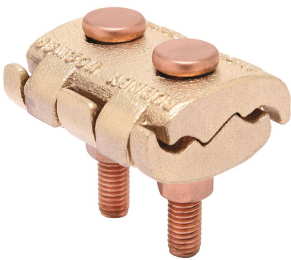

Features

- Type UC connector accommodates large range of conductors in either groove, reducing inventory requirements
- Interlocking finger design provides firm grip with maximum contact length
- High strength, corrosion resistant silicon bronze hardware

Application

For Range Of Copper

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	4/0 AWG
Conductor - Copper Solid Size	4/0 AWG
Range	
Conductor - Copper Str Size	4/0 AWG-500 kcmil
Range	
Conductor - Copper Str Size	• 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	2.75 in
Dimension - Height fraction	2-3/4 in
Dimension - B Length fraction	4-1/4 in
Package Weight	0.000 lb.
Dimension - Width inch	2.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	4.25 in
Dimension - Width fraction	2-1/2 in

Force Related

Installation Torque	480 LBS/in
Recommended in-lb	

General

Plated	N
Sub Brand	TAPIT
UPC	781810012901
Type	UC
Plating Type	Unplated
UPC 14 Digit GTIN	00781810012901

Logistics

Pallet Quantity	432
Carton Quantity	4

Product Assets

[Catalog \[English\]](#)