




UC2844, Parallel Clamp for Copper, 4/0 Str-1000 kcmil

By Burndy
Catalog # [UC2844](#)

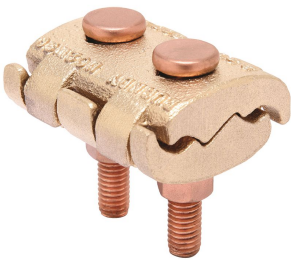

Parallel clamp for copper, 4/0 STR to 1000 kcmil, 4.25" L, 3.91" Height.

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size Range	4/0 AWG-1000 kcmil
-------------------------------------	--------------------

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Length	4.25 in
Dimension - Height inch	3.91 in
Dimension - B Length fraction	4-1/4 in
Package Weight	0.000 lb.

Dimension - Width inch	3.44 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	4.25 in
Height	3.91 in
Width	3.44 in
Dimensions	4.25 in x 3.44 in x 3.91 in

General

Plated	N
UPC	781810502495
Plating Type	Unplated
UPC 14 Digit GTIN	00781810502495

Logistics

Minimum Pack Quantity	50
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)