




BURNDY

UC2W30, Copper Parallel Groove Clamp

By Burndy

Catalog # [UC2W30](#)

CU Parallel Groove Clamp accommodates large number of CU Conductors, Conductor: 2 Sol. - 300 (Either Groove)

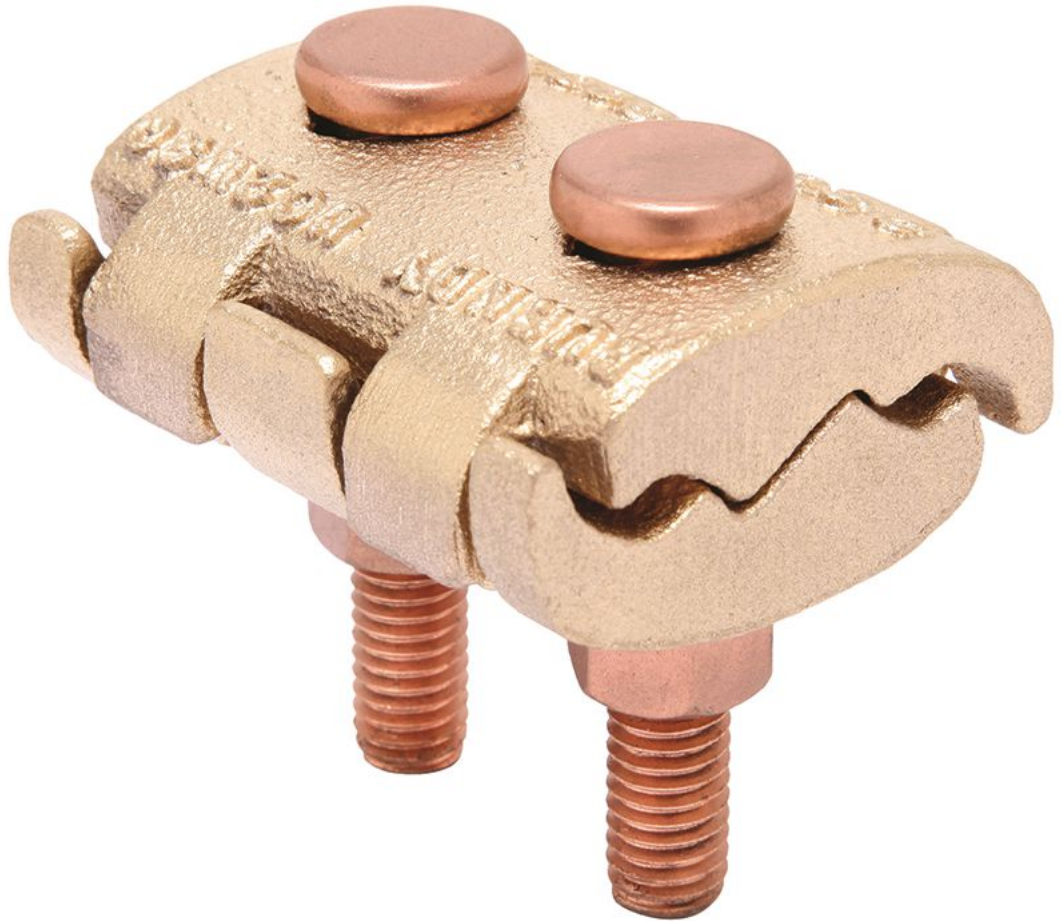

Features

- Type UC connector accommodates large range of conductors in either groove, reducing inventory requirements
- Interlocking finger design provides firm grip with maximum contact length
- High strength, corrosion resistant silicon bronze hardware

Application

For Range Of Copper

Specifications

Certification - ETL
No
Certification - UL Recognized
No
Standards - RoHS Compliance Status
EX
Certification - cULus
No
EU RoHS Indicator
Yes
UL Listed
No
Certification - CSA Approved
No

Conductor

Conductor - Copper Solid Size
2 AWG
Conductor - Copper Solid Size Range
2 AWG
Conductor - Copper Str Size Range
2 AWG-300 kcmil
Conductor - Copper Str Size

- 2 AWG
- 1 AWG
- 1/0
- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil
- 300 kcmil

Dimensions

Package Height
0.000 in
Dimension - Height mm
0 mm
Dimension - Height inch
2.18 in
Dimension - Height fraction
2-3/16 in
Dimension - B Length fraction
2-7/8 in
Package Weight
0.000 lb.
Package Length
0.000 in
Package Width
0.000 in
Dimension - B Length inch
2.88 in
Dimension - Width fraction
2 in

Force Related

Installation Torque Recommended in-lb
240 LBS/in

General

Plated
N
Sub Brand
TAPIT
UPC
781810012871
Type
UC
Plating Type
Unplated
UPC 14 Digit GTIN
00781810012871

Logistics

Pallet Quantity
1296
Carton Quantity
12

Product Assets

[Catalog \[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY_CA-UC2W30-SPEC-EN | REV 5/2026