


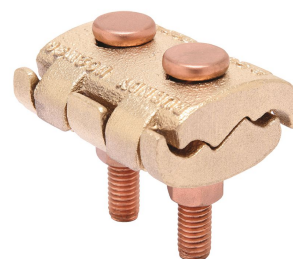

UC3040, Copper Parallel Groove Clamp, 300-800 kcmil - Either Groove

By Burndy
Catalog # [UC3040](#)

CU Parallel Groove Clamp accommodates large number of CU
Conductors, Conductor: 300 - 800 (Either Groove)



Features

- Parallel Groove Clamp, Type UC for Copper
- Type UC connectors accommodate a large range of conductors in either groove, reducing inventory necessary
- Interlocking finger design provides a firm grip with maximum contact length
- High strength, corrosion resistant silicon bronze hardware
- One wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	300 kcmil-800 kcmil
Conductor - Copper Str Size	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil • 800 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	3.31 in
Dimension - Height fraction	3-5/16 in
Dimension - B Length fraction	4-1/4 in
Package Weight	0.000 lb.
Dimension - Width inch	3.06 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	4.25 in
Dimension - Width fraction	3-1/16 in

Force Related

Installation Torque	480 LBS/in
Recommended in-lb	

General

Plated	N
UPC	781810012918
Material	Copper
Plating Type	Unplated
UPC 14 Digit GTIN	00781810012918

Logistics

Minimum Pack Quantity	4
Pallet Quantity	108
Carton Quantity	3

Product Assets

[Catalog \[English\]](#)