




UC3040W, Parallel Clamp, Run 300-800 kcmil, Tin Plated

By Burndy
Catalog # UC3040W

Parallel Clamp

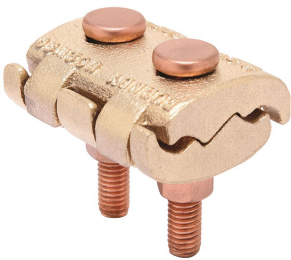

Features

- Parallel Groove Clamp, Type UC for Copper, Tin Plated
- Type UC connectors accommodate a large range of conductors in either groove, reducing inventory necessary
- Interlocking finger design provides a firm grip with maximum contact length
- High strength, corrosion resistant silicon bronze hardware
- One wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Plated	N
UPC	781810353110
Plating Type	Unplated
UPC 12 Digit	781810353110
UPC 14 Digit GTIN	00781810353110

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)