




UCG25R2R, Parallel Clamp, Aluminum

By Burndy
Catalog # [UCG25R2R](#)

Parallel Clamp, Cast Aluminum Alloy, 1.19" L, 1.71" Height, 1.46" W

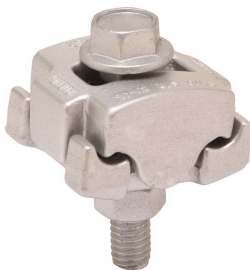

Features

- TAPIT Parallel Clamp
- High strength, high conductivity, non-copper bearing aluminum alloy
- Properly proportioned to minimize stress corrosion and deterioration by galvanic action
- Keying tabs on connector body halves prevent mismatching
- Square shank, high strength galvanized steel bolt allows one wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor - Copper Str Size B	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Str Size A Range	6 AWG-1/0
Conductor - Copper Solid Size A	6 AWG
Conductor - Copper Solid Size B	6 AWG
Conductor - Copper Solid Size A Range	6 AWG
Conductor - AAAC 5005 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil
Conductor - AAAC 5005 Size A Range	30.58 (7) kcmil-123.3 (7) kcmil

Conductor - AAAC 5005 Size B Range	30.58 (7) kcmil-77.47 (7) kcmil
Conductor - AAAC 6201 Size B Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AAAC 6201 Size A	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil
Conductor - Copper Solid Size B Range	6 AWG
Conductor - AAAC 6201 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil
Conductor - AAAC 6201 Size A Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AL Str Size A	• 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - AL Str Size B	• 6 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - AL Str Size A Range	6 AWG-1/0 AWG
Conductor - AAAC 5005 Size A	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil
Conductor - AL Str Size B Range	6 AWG-2 AWG
Conductor Type	• AL C Str-Size A • CU C Solid-Size A • CU C Str-Size A • AAAC C 5005-Size A • AAAC C 6201-Size A • AL C Str-Size B • CU C Solid-Size B • CU C Str-Size B • AAAC C 5005-Size B • AAAC C 6201-Size B
Conductor - Copper Str Size B Range	6 AWG-2 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	47.6 mm
Dimension - Height inch	1.71 in
Dimension - Height fraction	1-5/7 in
Dimension - B Length fraction	1-1/5 in
Package Weight	0.000 lb.
Dimension - Width inch	1.46 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.19 in
Dimension - Width fraction	1-1/2 in

Force Related

Installation Torque	240 LBS/in
Recommended in-lb	

General

Plated	N
Trade Name	TAPIT™
UPC	781810097755
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810097755

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)



A Hubbell brand