



UCG25RS, Aluminum Alloy Parallel Clamp

By Burndy
Catalog # [UCG25RS](#)

Multiple purpose parallel groove clamp made of high strength, high conductivity aluminum alloy. Hardware allows for one of two wrench installation,length:1-3/8",width:1-5/8".

Features

- Multi-purpose parallel groove clamp made of high strength, high conductivity, non-copper bearing aluminum alloy
- Properly proportioned to minimize stress corrosion and deterioration by galvanic action
- Interlocking fingers on connector body halves prevent mismatching
- Square shank, hex head, round collar, high strength galvanized steel bolt allows 1 or 2-wrench installation
- Supplied pre-filled with PENETROX™ joint compound and strip sealed

Application


For All Combinations Of Copper, Aluminum, ACSR, 6201 And 5005

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Size B	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 5005 Size A Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AAAC 5005 Size B Range	30.58 (7) kcmil-246.9 (7) kcmil
Conductor - AAAC 6201 Size B Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AAAC 6201 Size A	• 30.58 (7) kcmil • 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil
Conductor - AAAC 6201 Size B	• 30.58 (7) kcmil

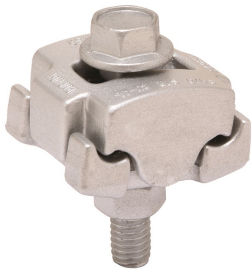


	• 48.69 (7) kcmil • 77.47 (7) kcmil • 123.3 (7) kcmil • 155.4 (7) kcmil • 195.7 (7) kcmil • 246.9 (7) kcmil
Conductor - AAAC 6201 Size A Range	30.58 (7) kcmil-123.3 (7) kcmil
Conductor - AL Str Size A	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - AL Str Size B	• 8 AWG • 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - AL Str Size A Range	8 AWG-1/0 AWG
Conductor - AL Str Size B Range	8 AWG-1/0 AWG
Conductor - Copper Str Size A	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor - Copper Str Size B	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor - Copper Str Size A Range	8 AWG-1/0
Conductor - AAAC 5005 Size A	• 30.58 (7) kcmil

Conductor Type	48.69 (7) kcmil 77.47 (7) kcmil 123.3 (7) kcmil - AL C Str-Size A - CU C Solid-Size A - CU C Str-Size A - AAAC C 5005-Size A - AAAC C 6201-Size A - AL C Str-Size B - CU C Solid-Size B - CU C Str-Size B - AAAC C 5005-Size B - AAAC C 6201-Size B
Conductor - Copper Str Size B Range	8 AWG-1/0

Dimensions

Package Height	0.000 in
Dimension - Height mm	53.1 mm
Dimension - Height inch	2.09 in
Dimension - Height fraction	2-1/8 in
Package Weight	0.000 lb.
Package Length	0.000 in

 

A Hubbell brand

Package Width	0.000 in
Dimension - Width fraction	1-5/7 in
Dimension - B Length fraction	1-3/8 in
Dimension - Width mm	43 mm
Dimension - Width inch	1.71 in
Dimension - B Length inch	1.41 in

General

Trade Name	TAPIT™
Plated	N
Sub Brand	TAPIT
UPC	781810097809
Type	UCG-RS
Material	Aluminum
Plating Type	Unplated
UPC 14 Digit GTIN	00781810097809

Logistics

Pallet Quantity	1
Carton Quantity	100

Product Assets

[Catalog \[English\]](#)